



TIMKEN

HUBCAPS AND WHEEL END ACCESSORIES INTERCHANGE

HUBCAPS

DESCRIPTION	APPLICATION	TIMKEN	STEMCO	SKF	NATIONAL
Cast Aluminum for Oil, Replaceable Window, Economy Trailer Model	5.5" Bolt Circle, 6 Hole, with Gasket, Pipe Plug, and Orange Vent Plug	81909	343-4009	1843	HU-009A
Cast Aluminum for Oil, Bulk Case of 24 Units, Economy Trailer Model	5.5" Bolt Circle, 6 Hole, with Gasket, Pipe Plug, and Orange Vent Plug	81909B	343-4009	1843	HU-009A
Cast Aluminum for Oil, Press Fit Window, Premium Trailer Model	5.5" Bolt Circle, 6 Hole, with Gasket, Pipe Plug, and Orange Vent Plug	81009	343-4009	1843	HU-009A
Cast Aluminum for Oil, Press Fit Window, Premium Steer Axle Model	4.5" Bolt Circle, 6 Hole, with Gasket, Pipe Plug, and Orange Vent Plug	81024	343-4024	1811	HU-024A
Cast Aluminum for Oil, Press Fit Window, Premium TP Axle Model	Screw On with Rubber O Ring, Pipe Plug, and Orange Vent Plug	81075	343-4075	1682	HU-075A
Cast Aluminum for Oil, Press Fit Window, Premium TN Axle Model	6.75" Bolt Circle, 6 Hole, with Gasket, Pipe Plug, and Orange Vent Plug	81195	343-4195	1696	
Clear Polycarbonate, Propar (TP) Axle Model	Screw On with Rubber O Ring and Orange Vent Plug	85075	640-0003	1282	H-075
Stamped Steel Oil Hub Cap, Powder Coat Painted	5.5" Bolt Circle, 6 Hole With Window, Premium Cork Gasket and Orange Plug	86009		1743	
Stamped Steel Grease Hub Cap, Powder Coat Painted	5.5" Bolt Circle, 6 Hole With Bronze Vent and Premium Cork Gasket	87009	340-5096	1753	
Stamped Steel Grease Hub Cap, Derby Style, Unpainted	5.5" Bolt Circle, 6 Hole Ventless, With Premium Cork Gasket	88009	340-5097		

HUBCAP ACCESSORIES

DESCRIPTION	APPLICATION	TIMKEN	STEMCO	SKF	NATIONAL
6 Hole Gasket for Hub Caps	5.5" Bolt Circle, 6 Hole	61009	330-3009	450751	
Universal Gasket for Hub Caps	5.5" Bolt Circle, 12 Hole, Universal, for 4, 5 and 6 Hole Hub Caps	61067	330-3067	450782	733067
Universal Gasket for Hub Caps, Bulk Pack	5.5" Bolt Circle, 12 Hole, Universal, for 4, 5 and 6 Hole Hub Caps	61067B	330-3067	450782	733067
6 Hole Premium Cork Rubber Gasket for Stamped Steel Caps	5.5" Bolt Circle, 6 Hole, for 6 Hole Stamped Steel Hub Caps	62209			
Orange Universal Plug	Trailer and Steer Hub Cap Plugs	64999	359-5990		
Orange Universal Plug, Bulk Pack 100	Trailer and Steer Hub Cap Plugs	64999B			
3.5" Diameter Window Replacement Kit	4009 Window, Window and Flange Gasket, Orange Vent Plug and Screws	74009	359-5995		
3.5" Diameter Replacement Window for Hubo	Hubodometer Window	74009H	359-6117		

HOT DOTS (10 Hot Dots per pack)

DESCRIPTION	TIMKEN
Hot Dots - 1 Pack	43250
Hot Dots - 10 Pack	43250R
Hot Dots - 100 Pack	43250B



TIMKEN

HUBCAPS AND WHEEL END ACCESSORIES INTERCHANGE

DIGITAL HUBODOMETERS

TIMKEN	TRISEAL	VEEDER-ROOT	STEMCO
47001	47000	RT1000-000	600-5499

ANALOG HUBODOMETERS

TIRE SIZE	TREAD SIZE	MILES			KILOMETERS		
		TIMKEN	VEEDER ROOT	STEMCO	TIMKEN	VEEDER ROOT	STEMCO
10" x 22"	Extra High	46468	777717-465	650-0581	46294	777727-294	650-0526
11" x 24.5"	Extra High	46468	777717-465	650-0581	46294	777727-294	650-0526
11" x 22"	Standard	46468	777717-465	650-0583	46294	777727-294	650-0528
12" x 24.5"	Standard	46468	777717-465	650-0583	46294	777727-294	650-0528
10" x 20"	High Tread	46480	777717-490	650-0587	46308	777727-306	650-0532
11" x 22.5"	High Tread	46480	777717-490	650-0587	46308	777727-306	650-0532
10" x 20R"	Standard	46500	777717-500	650-0598	46312	777727-310	650-0537
11" x 22.5"	Standard	46500	777717-500	650-0598	46312	777727-310	650-0537
285/75R-24.5" STD	Standard	46500	777717-500	650-0601	46312	777727-310	650-0539
9" x 20"	High Tread	46500	777717-500	650-0601	46312	777727-310	650-0539
10" x 22.5"	High Tread	46500	777717-500	650-0601	46312	777727-310	650-0539
275/80R-24.5"	High Tread	46510	777717-510	650-0593	46315	777727-316	650-0532
295/75R-22.5"	Standard	46525	777717-520	650-0610	46325	777727-326	650-0545
275/80R-22.5"	Low Tread	46525	777717-520	650-0608	46325	777727-326	650-0545
9" x 20"	Standard	46525	777717-525	650-0608	46325	777727-326	650-0545
10" x 22.5"	Standard	46525	777717-525	650-0608	46325	777727-326	650-0545
445/50R22.5"	Standard	46525	777717-525	650-0608	46325	777727-326	650-0545

UNITIZED SPINDLE NUTS

DESCRIPTION	APPLICATION	TIMKEN	STEMCO
3.480" – 12Trailer Axle	Pro-Par Trailer Axle, Meritor TP, Eaton P-22	412-3480	447-4723
2.625" – 16Trailer Axle	17,000 – 22,500# Meritor, Dana, Eaton	416-2625	447-4743
1.5" – 18 Front (Steer) Axle	2,000# Meritor, Ford, Eaton	418-1500	448-4837
1.5" – 12TPI Steer	12,000# Meritor, Navistar	412-1500	448-4836
3.25" – 12TPI Drive	34,000 – 46,000# Eaton, Meritor, Dana, Navistar, 50,000# Mack	412-3250	448-4973



TIMKEN

HUBCAPS AND WHEEL END ACCESSORIES INTERCHANGE


HUBODOMETER BRACKETS

DESCRIPTION	BOLT CIRCLE	STUD SIZE	HEIGHT	TYPE	TIMKEN	STEMCO CROSS
Hubodometer Bracket	6-3/8" – 6-1/2"	1/2" – 9/16"	1-11/16"	A	660003	610-0003
Hubodometer Bracket	7-1/2"	5/8"	1-9/16"	A	660008	610-0008
Hubodometer Bracket	7"	5/8"	1-11/16"	A	660011	610-0006
Hubodometer Bracket	7"	3/4"	1-11/16"	A	660012	610-0007
Hubodometer Bracket	6-1/2"	1/2"	4-1/2"	A	660013	610-0058
Hubodometer Bracket	5-1/2"	7/16"	4"	A	660014	610-0013
Hubodometer Bracket – 3 Leg	5-1/2"	5/16"	5"	C	660028	610-6028
Hubodometer Bracket – 4 Leg	6-3/4"	5/16"	5"	D	660084	610-0084
Hubodometer Bracket – 3 Leg	6-3/4"	5/16"	5"	C	660085	610-0084
Hubodometer Bracket	5-1/2"	5/16"	3-1/2"	A	660901	610-0065
Hubodometer Bracket – Universal	5-1/2" – 7-1/2"	1/2"	1-3/4"	B	660904	610-0011


TYPE A



TYPE B

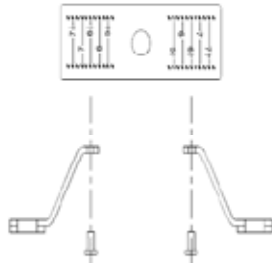

TYPE C

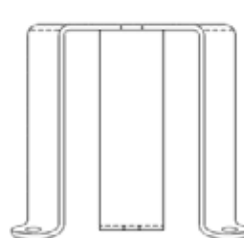

TYPE D



HUBODOMETER HUBCAPS FOR TRAILER APPLICATIONS

DESCRIPTION	BOLT CIRCLE	NO. OF BOLTS	BOLT DIAMETER	ALUMINUM EQUIV.	GASKET	TIMKEN
Trailer	5.5"	6	5/16"	81009	61009	83009
Trailer	5.5"	5	5/16"	81013	61067	83013
Trailer	5.5"	3	3/8"	81014	61014	83014
Trailer	5.88"	6	3/8"	81025	61025	83025
Trailer	5.5"	6	5/16"	81046	61067	83046
Trailer	6"	6	3/8"	81059	61056	83059