

Timken® Spherical Roller Bearing Solid-Block Housed Unit

Dimensional Interchange


TIMKEN



Dodge Part Number	Dodge Part Description	TIMKEN				
Assembly	Special Duty	Timken Housed Unit Assembly	Open End Cover Urethane**	Closed End Cover Urethane**	Open End Cover Steel**	Closed End Cover Steel**
066214	P2B-SD-107	TAAASD09K107ST	CKDR107	CS09	CK09T107S	CS09STEEL
066300	P2B-SD-108	TAAASD09K108ST	CKDR108	CS09	CK09T108S	CS09STEEL
066216	P2B-SD-111	TAAASD10K111ST	CKDR111	CS10	CK10T111S	CS10STEEL
066301	P2B-SD-112	TAAASD10K112ST	CKDR112	CS10	CK10T112S	CS10STEEL
066218	P2B-SD-115	TAAASD11K115ST	CKDR115	CS11	CK11T115S	CS11STEEL
066302	P2B-SD-200	TAAASD11K200ST	CKDR200	CS11	CK11T200S	CS11STEEL
066220	P2B-SD-203	TAAASD13K203ST	CKDR203	CS13	CK13T203S	CS13STEEL
066303	P2B-SD-204	TAAASD13K204ST	CKDR204	CS13	CK13T204S	CS13STEEL
066222	P2B-SD-207	TAAASD15K207ST	CKDR207	CS15	CK15T207S	CS15STEEL
066246	P2B-SD-208	TAAASD15K208ST	CKDR208	CS15	CK15T208S	CS15STEEL
066230	P2B-SD-215	TAAASD17K215ST	CKDR215	CS17	CK17T215S	CS17STEEL
066305	P2B-SD-300	TAAASD17K300ST	CKDR300	CS17	CK17T300S	CS17STEEL
066234	P2B-SD-307	TAAASD20K307ST	CKDR307	CS20	CK20T307S	CS20STEEL
066236	P2B-SD-308	TAAASD20K308ST	CKDR308	CS20	CK20T308S	CS20STEEL
066224	P4B-SD-207	TAA4SD15K207ST	CKDR207	CS15	CK15T207S	CS15STEEL
066244	P4B-SD-208	TAA4SD15K208ST	CKDR208	CS15	CK15T208S	CS15STEEL
066231	P4B-SD-215	TAA4SD17K215ST	CKDR215	CS17	CK17T215S	CS17STEEL
066366	P4B-SD-300	TAA4SD17K300ST	CKDR300	CS17	CK17T300S	CS17STEEL
066235	P4B-SD-307	TAA4SD20K307ST	CKDR307	CS20	CK20T307S	CS20STEEL
066371	P4B-SD-308	TAA4SD20K308ST	CKDR308	CS20	CK20T308S	CS20STEEL
066238	P4B-SD-315	TAA4SD22K315ST	CKDR315	CS22	CK22T315S	CS22STEEL
066375	P4B-SD-400	TAA4SD22K400ST	CKDR400	CS22	CK22T400S	CS22STEEL
066240	P4B-SD-407	TAA4SD26K407ST	CKDR407	CS26	CK26T407S	CS26STEEL
066377	P4B-SD-408	TAA4SD26K408ST	CKDR408	CS26	CK26T408S	CS26STEEL
066242	P4B-SD-415	TAA4SD28K415ST	CKDR415	CS28	CK28T415S	CS28STEEL
066378	P4B-SD-500	TAA4SD28K500ST	CKDR500	CS28	CK28T500S	CS28STEEL
066379	P4B-SD-507	TAA4SD32K507SO	N/A	N/A	CK32T507S	CS32STEEL
	P4B-SD-508	TAA4SD32K508SO	N/A	N/A	CK32T508S	CS32STEEL
066381	P4B-SD-515	TAA4SD34K515SO	N/A	N/A	CK34T515S	CS34LSTEEL
066382	P4B-SD-600	TAA4SD34K600SO	N/A	N/A	CK34T600S	CS34LSTEEL
	P4B-SD-607	TAA4SD36K607SO	N/A	N/A	CK36T607S	CS36STEEL
066384	P4B-SD-608	TAA4SD36K608SO	N/A	N/A	CK36T608S	CS36STEEL
066385	P4B-SD-615	TAA4SD38K615SO	N/A	N/A	CK38T615S	CS38STEEL
066386	P4B-SD-700	TAA4SD38K700SO	N/A	N/A	CK38T700S	CS38STEEL
066388	P4B-SD-715	TAA4SD44K715SO	N/A	N/A	CK44T715S	CS44STEEL
066389	P4B-SD-800	TAA4SD44K800SO	N/A	N/A	CK44T800S	CS44STEEL

Labyrinth Seals - DuPont™ Teflon®

- High-speed applications.
- Superior in heavily contaminated conditions.
- Able to operate at high temperatures.
- Resistant to most chemicals.
- Abrasion-resistant.

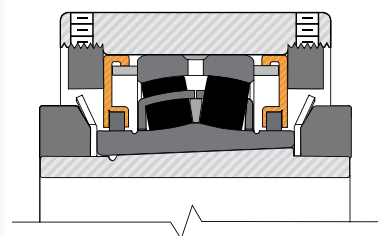

TAA/DAA - Double Nut

Tapered Adapter Lock

- Extreme heavy duty
- Increased shaft contact
- Accommodates undersized shafting
- Easy to install without the need to measure internal clearance
- Mechanical withdrawal for easier removal

ALSO AVAILABLE

Triple-Lip Seals - Nitrile

- Self-purging.
- Excellent in wet and dirty applications.
- Chemical- and corrosion-resistant

Triple-Lip Seals - Urethane

- All the benefits of Nitrile, plus more resistant to abrasion.

*Nomenclature shown with Double-Nut Tapered Adapter
Single adapter will begin with just one A = TASD

**End covers optional



Dodge Part Number	Dodge Part Description	TIMKEN				
2 Bolt Pillow - Blocks	Type C	Timken Housed Unit Assembly	Open End Cover Urethane**	Closed End Cover Urethane**	Open End Cover Steel**	Closed End Cover Steel**
065290	P2B-C-107	TAASD09K107ST	CKDR107	CS09	CK09T107S	CS09STEEL
065312	P2B-C-108	TAASD09K108ST	CKDR108	CS09	CK09T108S	CS09STEEL
065291	P2B-C-111	TAASD10K111ST	CKDR111	CS10	CK10T111S	CS10STEEL
065238	P2B-C-112	TAASD10K112ST	CKDR112	CS10	CK10T112S	CS10STEEL
065292	P2B-C-115	TAASD11K115ST	CKDR115	CS11	CK11T115S	CS11STEEL
065313	P2B-C-200	TAASD11K200ST	CKDR200	CS11	CK11T200S	CS11STEEL
065293	P2B-C-203	TAASD13K203ST	CKDR203	CS13	CK13T203S	CS13STEEL
065314	P2B-C-204	TAASD13K204ST	CKDR204	CS13	CK13T204S	CS13STEEL
065294	P2B-C-207	TAASD15K207ST	CKDR207	CS15	CK15T207S	CS15STEEL
065315	P2B-C-208	TAASD15K208ST	CKDR208	CS15	CK15T208S	CS15STEEL
065296	P2B-C-215	TAASD17K215ST	CKDR215	CS17	CK17T215S	CS17STEEL
065316	P2B-C-300	TAASD17K300ST	CKDR300	CS17	CK17T300S	CS17STEEL
065297	P2B-C-307	TAASD20K307ST	CKDR307	CS20	CK20T307S	CS20STEEL

Dodge Part Number	Dodge Part Description	TIMKEN				
Assembly	Double Interlock	Timken Housed Unit Assembly	Open End Cover Urethane**	Closed End Cover Urethane**	Open End Cover Steel**	Closed End Cover Steel**
023331	P2B-DI-107	TAADI09K107ST	CKDR107	CS09	CK09T107S	CS09STEEL
023332	P2B-DI-108	TAADI09K108ST	CKDR108	CS09	CK09T108S	CS09STEEL
023334	P2B-DI-111	TAADI10K111ST	CKDR111	CS10	CK10T111S	CS10STEEL
023335	P2B-DI-112	TAADI10K112ST	CKDR112	CS10	CK10T112S	CS10STEEL
023337	P2B-DI-115	TAADI11K115ST	CKDR115	CS11	CK11T115S	CS11STEEL
023338	P2B-DI-200	TAADI11K200ST	CKDR200	CS11	CK11T200S	CS11STEEL
023339	P2B-DI-203	TAADI13K203ST	CKDR203	CS13	CK13T203S	CS13STEEL
023340	P2B-DI-204	TAADI13K204ST	CKDR204	CS13	CK13T204S	CS13STEEL
023341	P2B-DI-207	TAADI15K207ST	CKDR207	CS15	CK15T207S	CS15STEEL
023342	P2B-DI-208	TAADI15K208ST	CKDR208	CS15	CK15T208S	CS15STEEL
023345	P2B-DI-215	TAADI17K215ST	CKDR215	CS17	CK17T215S	CS17STEEL
023346	P2B-DI-300	TAADI17K300ST	CKDR300	CS17	CK17T300S	CS17STEEL
023349	P2B-DI-307	TAADI20K307ST	CKDR307	CS20	CK20T307S	CS20STEEL
023350	P2B-DI-308	TAADI20K308ST	CKDR308	CS20	CK20T308S	CS20STEEL
023352	P4B-DI-207	TAA4DI15K207ST	CKDR207	CS15	CK15T207S	CS15STEEL
023353	P4B-DI-208	TAA4DI15K208ST	CKDR208	CS15	CK15T208S	CS15STEEL
023356	P4B-DI-215	TAA4DI17K215ST	CKDR215	CS17	CK17T215S	CS17STEEL
023357	P4B-DI-300	TAA4DI17K300ST	CKDR300	CS17	CK17T300S	CS17STEEL
023360	P4B-DI-307	TAA4DI20K307ST	CKDR307	CS20	CK20T307S	CS20STEEL
023361	P4B-DI-308	TAA4DI20K308ST	CKDR308	CS20	CK20T308S	CS20STEEL
023362	P4B-DI-315	TAA4DI22K315ST	CKDR315	CS22	CK22T315S	CS22STEEL
023363	P4B-DI-400	TAA4DI22K400ST	CKDR400	CS22	CK22T400S	CS22STEEL
023364	P4B-DI-407	TAA4DI26K407ST	CKDR407	CS26	CK26T407S	CS26STEEL
023365	P4B-DI-408	TAA4DI26K408ST	CKDR408	CS26	CK26T408S	CS26STEEL
023366	P4B-DI-415	TAA4DI28K415ST	CKDR415	CS28	CK28T415S	CS28STEEL
023367	P4B-DI-500	TAA4DI28K500ST	CKDR500	CS28	CK28T500S	CS28STEEL
023368	P4B-DI-507	TAA4DI32K507SO	N/A	N/A	CK32T507S	CS32STEEL
	P4B-DI-508	TAA4DI32K508SO	N/A	N/A	CK32T508S	CS32STEEL
023369	P4B-DI-515	TAA4DI34K515SO	N/A	N/A	CK34T515S	CS34LSTEEL
	P4B-DI-600	TAA4DI34K600SO	N/A	N/A	CK34T600S	CS34LSTEEL
	P4B-DI-607	TAA4DI36K607SO	N/A	N/A	CK36T607S	CS36STEEL
	P4B-DI-608	TAA4DI36K608SO	N/A	N/A	CK36T608S	CS36STEEL
	P4B-DI-615	TAA4DI38K615SO	N/A	N/A	CK38T615S	CS38STEEL
	P4B-DI-700	TAA4DI38K700SO	N/A	N/A	CK38T700S	CS38STEEL
	P4B-DI-715	TAA4DI44K715SO	N/A	N/A	CK44T715S	CS44STEEL
	P4B-DI-800	TAA4DI44K800SO	N/A	N/A	CK44T800S	CS44STEEL

The Timken team applies their know-how to improve the reliability and performance of machinery in diverse markets worldwide. The company designs, makes and markets bearings, gear drives, automated lubrication systems, belts, brakes, clutches, chain, couplings, linear motion products and related power transmission rebuild and repair services.

Stronger. By Design.

www.timken.com