

# TIMKEN

## Delivering Reliable and Durable Performance.

### Timken® Driveline Center Support Bearings for Light Vehicles


Timken delivers outstanding reliability and durable performance in our driveline center support bearings (frequently referred to as “hanger bearings”). Easy to install, Timken® driveline center support bearings are designed for superior performance, regardless of operating conditions.

**RELIABLE:** Bearing inserts are pre-greased and pre-sealed with an additional grease barrier between the bearing retainer caps and sealed bearing to extend bearing life.

**DURABLE:** Heavy-duty bracket made from reinforced heavy-gauge cold-rolled steel imparts strength and durability. The rubber cushion provides support while it absorbs and isolates vibrations, extending service life in rough environments.

**PERFORMANCE:** Driveline center support bearings are rigorously inspected to meet Timken performance and quality standards.

**INTERCHANGEABLE:** Driveline center support bearings interchange with all major light vehicle applications for easy installation and dependable operation.

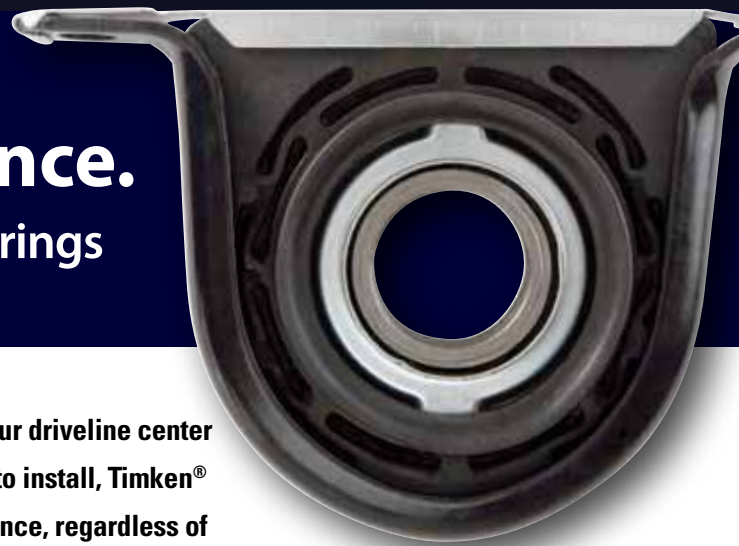

Stronger. **Value.**

- *Simplifies installation*
- *Interchanges with all major light vehicle applications*

# Timken Interchange Guide

Timken® Light Vehicle Part Number	DT Components® Part Number	Dana-Spicer® Part Number	Federal Mogul® Part Number	Meritor® Part Number	NEAPCO® Part Number	SKF® Part Number
HB13	HB13	211502X	HB13	–	N212804	HB1280-40
HB206FF	HB210527-X	210527-X	HB-206-FF	CB210527X	N210527X	HB206-FF
HB26	HB26	211750-1X	HB-26	–	N213805	HB1380-50
HB31	HB31	–	HB-31	–	N223804	HB2380-40
HB88107A	HB88107-A	211130X	HB-88107-A	CB211187X	N211139X	HB88107-A
HB88107B	HB210088-1X	210088-1X	HB-88107-B	CB2100881X	N210088-1X	HB88107-B
HB88107C	HB210090-1X	210090-1X	HB-88107-C	CB2100901X	N210090-1X	HB88107-C
HB88107D	HB210367-1X	210367-1X	HB-88107-D	CB2103671X	N210367-1X	HB88107-D
HB88107E	HB210370-1X	210370-1X	HB-88107-E	CB2103701X	N210370-1X	HB88107-E
HB88108D	HB211848-1X	211848-1X	HB-1650-10	–	N211848-1X	HB88108-D
HB88508	HB88508	211098-1X	HB-88508	CB3100011X	N211098-1X	HB88508
HB88508A	HB88508-A	211260X	HB-88508-A	CB211016X	N211016X	HB88508-A
HB88508AA	HB210873-1X	210873-1X	HB-88508-AA	CB2108731X	N210873-1X	HB88508-AA
HB88508AB	HB210866-1X	210866-1X	HB-88508-AB	CB2108661X	N210866-1X	HB88508-AB
HB88508B	HB210433-1X	210433-1X	HB-88508-B	CB210433-1X	N210433-1X	HB88508-B
HB88508C	HB210140-1X	210140-1X	HB-88508-C	CB2101401X	N210140-1X	HB88508-C
HB88508D	HB210144-1X	210144-1X	HB-88508-D	CB210144-1X	N210144-1X	HB88508-D
HB88508E	HB210391-1X	210391-1X	HB-88508-E	CB2103911X	N210391-1X	HB88508-E
HB88509	HB88509	210969-1X	HB-88509	CB3100071X	N210969X	HB88509
HB88509A	HB210084-2X	210084-2X	HB-88509-A	CB2100842X	N210084-2X	HB88509-A
HB88509C	HB210207-1X	210207-1X	HB-88509-C	CB2102071X	N210207-1X	HB88509-C
HB88510	HB210121-1X	210121-1X	HB-88510	CB2101211X	N210121-1X	HB88510
HB88510S	HB210881-1X	210881-1X	HB-88510-S	CB2108811X	N210881-1X	HB88510-S
HB88512AHD	HB210661-1X	210661-1X	HB-88512-AHD	CB2106611X	N210661-1X	HB88512-A
HB88512ASHD	HB210875-1X	210875-1X	HB-88512-AS	CB2108751X	N210875-1X	HB88512-AS
HBD206FF	HB211590-1X	211590-1X	HBD-206-FF	–	N211590-1X	HB209-KF
HB6	HB6	–	HB-6	–	N212803	HB1280-30

10M 07-13-29 Order No. 10650 | Timken® is a registered trademark of The Timken Company. | © 2013 The Timken Company | Printed in U.S.A.  
All other trademarks are the property of their respective owners.

Contact a Timken sales representative today to discover how our driveline center support bearings can keep your vehicle on the road. (866) 9-TIMKEN (984-6536).

# TIMKEN

The Timken team applies their know-how to improve the reliability and performance of machinery in diverse markets worldwide. The company designs, makes and markets high-performance steel as well as mechanical components, including bearings, gears, chain and related mechanical power transmission products and services.

[www.timken.com](http://www.timken.com)



Stronger. Commitment. Stronger. Value. Stronger. Worldwide. Stronger. Together. | Stronger. By Design.